

Part No: 416-015F

Fabricated Fittings

Elbow

Desc: 1-1/2 PVC 22-1/2 ELL SOC SCH40 FAB

MSRP: 43.86

Part Code: 047

Weight(lbs): 0.223


Weight(kg): 0.101

Weight(gm): 101

Size: 1-1/2

Color: WHITE

Material: PVC

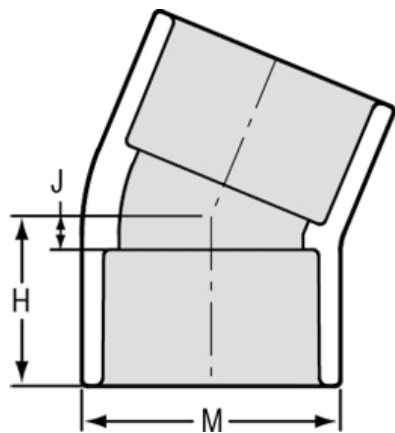

M = 2-3/16

J = 5/8

H = 2-1/8

Schedule SCH 40

Angle 22-1/2 Degree

Connection Socket X Socket

Type Standard

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

