

Part No: 416-025F

Fabricated Fittings

Elbow

Desc: 2-1/2 PVC 22-1/2 ELL SOC SCH40 FAB

MSRP: 53.62

Part Code: 047

Weight(lbs): 0.664


Weight(kg): 0.301

Weight(gm): 301

Size: 2-1/2"

Color: WHITE

Material: PVC

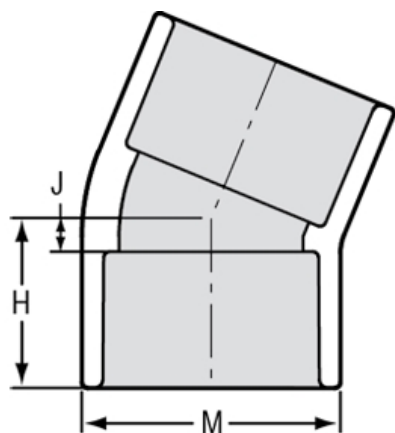

H = 2-13/16

J = 13/16

M = 3- 1/4

Schedule SCH 40

Angle 22-1/2 Degree

Connection Socket X Socket

Type Standard

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

