

**Part No:** 417-020UV

**Schedule 40 UVR**

**Elbow**

**Desc:** 2 PVC UVR 45 ELL SOC SCH40

**MSRP:** 21.58

**Part Code:** 042

**Weight(lbs):** 0.284

**Weight(kg):** 0.129

**Weight(gm):** 129


**Size:** 2"

**Color:** BEIGE

**Material:** PVC UVR

**Connection** Socket x Socket

**Type** 45° Elbow

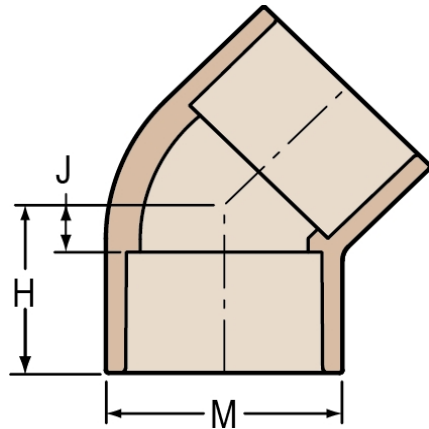

**H** = 2- 1/16

**J** = 11/16

**M** = 2- 3/4

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

