

Part No: 417-040L

Schedule 40 Clear

Elbow

Desc: 4 PVC 45 ELL SOC SCH40 CLEAR

MSRP: 581.12

Part Code: 039

Weight(lbs): 1.243

Weight(kg): 0.564

Weight(gm): 564


Size: 4"

Color: CLEAR

Material: PVC Clear

Connection Socket x Socket

Type 45° Elbow

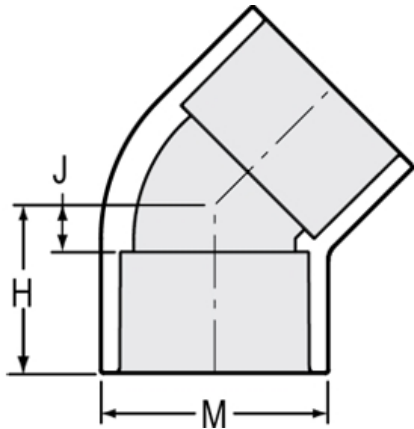

H = 3-1/8

J = 1-3/32

M = 5

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

