

Part No: 4199-005BRG

EverTUFF® CTS

Union

Desc: 1/2 CTS CPVC UNION W/GSK SOCXNPSC EPDM

MSRP: 36.37

Part Code: 033

Weight(lbs): 0.227


Weight(kg): 0.103

Weight(gm): 103

Size: 1/2"

Color: TAN

Material: CPVC

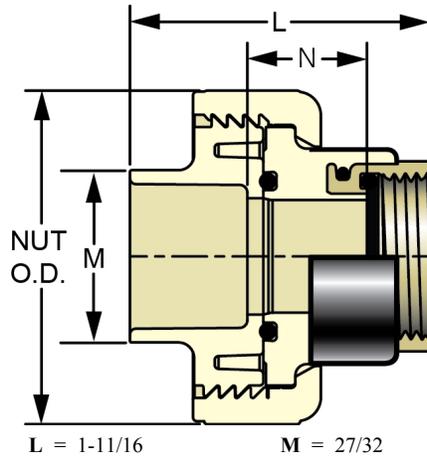

Connection Socket x Gasket Fipt
Type Union
O-Ring EPDM
NSF® Certified LEAD FREE
Pressure Rating 100 psi @ 180° F

L = 1-11/16

M = 27/32


N = 3/4

NUT = 2- 1/8
O.D.

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L** = Overall length of fittings; ± 1/16 inch.
- M** = Outside diameter of socket/thread hub; ± 1/16 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W** = Height of cap; ± 1/16 inch

Typical Molded Dimension References

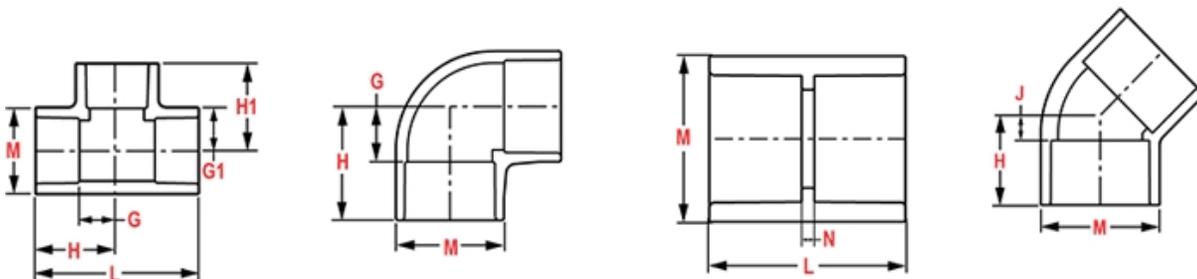

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006