

Part No: 4199-010BRG

EverTUFF® CTS

Union

Desc: 1 CTS CPVC UNION W/GSK SOCXNPSC EPDM

MSRP: 94.54

Part Code: 033

Weight(lbs): 0.403


Weight(kg): 0.183

Weight(gm): 183

Size: 1"

Color: TAN

Material: CPVC

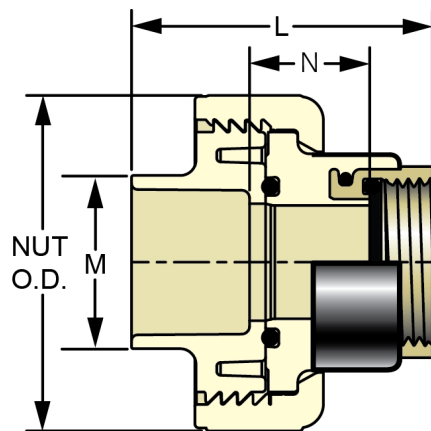

L = 2-3/8

M = 1-3/8

N = 15/16

NUT = 2-21/32
O.D.

Connection Socket x Gasket Fipt

Type Union

O-Ring EPDM

NSF® Certified LEAD FREE

Pressure Rating 100 psi @ 180° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

