

Part No: 420-700F

Fabricated Fittings

Cross

Desc: 14X10 PVC RED CROSS SOC SCH40 FAB

MSRP: 2830.66

Part Code: 047

Weight(lbs): 68.7


Weight(kg): 31.162

Weight(gm): 31162

Size: 14"X14"X10"X10"

Color: WHITE

Material: PVC

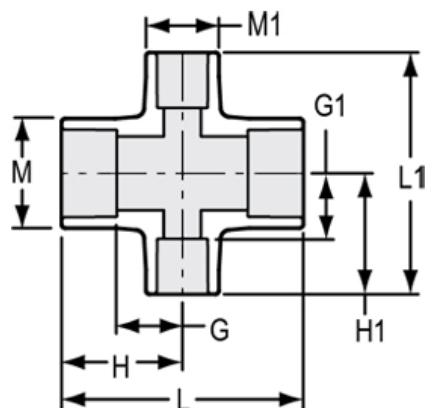

Schedule SCH 40

Connection Socket X Socket

Type Reduction

 $G = 10 - 3/8$
 $G1 = 10 - 15/16$
 $H = 17 - 3/8$
 $H1 = 16 - 3/16$
 $L = 34 - 3/4$
 $L1 = 32 - 3/8$
 $M = 14 - 7/8$
 $M1 = 11 - 1/2$

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

