

Part No: 4206-131

FlameGuard®

Elbow

Desc: 1X3/4 CPVC FLAMEGUARD 90 ELL SOC

MSRP: 7.07

Part Code: 070

Weight(lbs): 0.115

Weight(kg): 0.052

Weight(gm): 52


Size: 1"X3/4"

Color: ORANGE

Material: CPVC

Connection Socket x Socket (90°)

Type Reduction

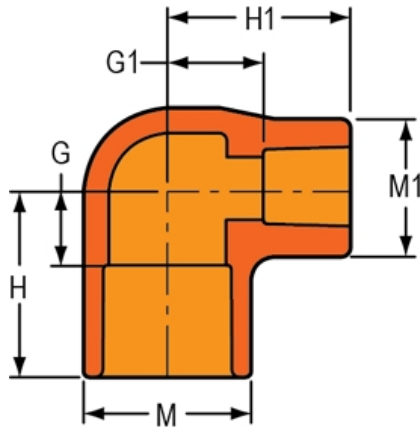

$$G = 21/32$$

$$G1 = 13/16$$

$$H = 1-25/32$$

$$H1 = 1-13/16$$

$$M = 1-19/32$$

$$M1 = 1-5/16$$

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

