

Part No: 4207-166GSR

FlameGuard®

SofTorque™ Sprinkler Head Fittings

Desc: 1-1/4X1/2 CPVC GSK SEAL 90 ELL SOCXSRNPS

MSRP: 11.35

Part Code: 076

Weight(lbs): 0.223

Weight(kg): 0.101

Weight(gm): 101

Size: 1-1/4 X 1/2

Color: ORANGE


Material: CPVC

Connection Socket x SR Fipt (Gasket)

Type 90° Elbow Head Adapter

NSF® Certified LEAD FREE

NOTE Use NO Thread Sealant

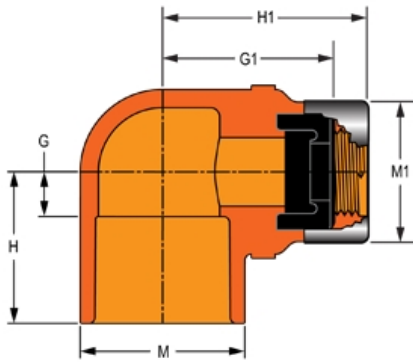

G = 7/16

G1 = 1-1/2

H = 1-11/16

H1 = 2-1/16

M = 2

M1 = 1-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

