

Part No: 427-040

Schedule 40 White

Elbow

Desc: 4 PVC 45 ST ELL SPIGOTXSOC SCH40

MSRP: 54.89

Part Code: 040

Weight(lbs): 2.152

Weight(kg): 0.976

Weight(gm): 976

Size: 4"


Color: WHITE

Material: PVC

Connection Spigot x Socket

Angle 45°

Type Standard

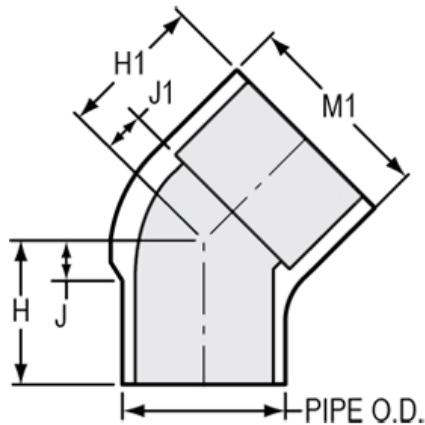

H = 3-7/8

H1 = 3-11/32

J = 1-5/8

J1 = 1-3/32

M1 = 5-1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

