

Part No: 427-060

Schedule 40 White

Elbow

Desc: 6 PVC 45 ST ELL SPIGOTXSOC SCH40

MSRP: 169.53

Part Code: 040

Weight(lbs): 5.732

Weight(kg): 2.6

Weight(gm): 2600

Size: 6"


Color: WHITE

Material: PVC

Connection Spigot x Socket

Angle 45°

Type Standard

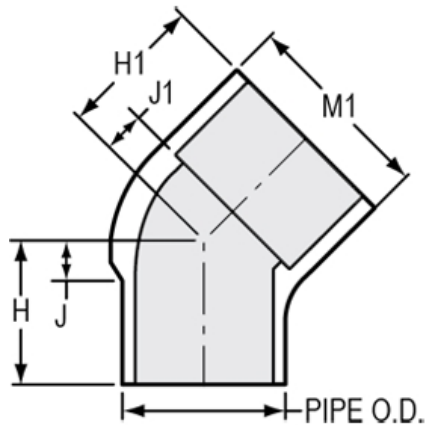

H = 5-1/8

H1 = 4-3/4

J = 2-1/8

J1 = 1-3/4

M1 = 7-19/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

