

**Part No:** 429-007UV

**Schedule 40 UVR**

**Coupling**

**Desc:** 3/4 PVC UVR COUPLING SOC SCH40

**MSRP:** 4.96

**Part Code:** 042

**Weight(lbs):** 0.049


**Weight(kg):** 0.022

**Weight(gm):** 22

**Size:** 3/4"

**Color:** BEIGE

**Material:** PVC

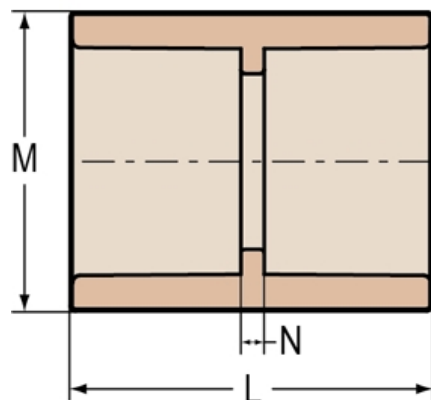

**Connection** Socket x Socket

**Type** Coupling

**L** = 2- 3/32

**M** = 1- 5/16

**N** = 3/32

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

