

**Part No:** 429-012G

**Schedule 40 Gray**

**Coupling**

**Desc:** 1-1/4 PVC COUPLING SCH40 GRAY

**MSRP:** 2.58

**Part Code:** 043

**Weight(lbs):** 0.115


**Weight(kg):** 0.052

**Weight(gm):** 52

**Size:** 1-1/4"

**Color:** GRAY

**Material:** PVC

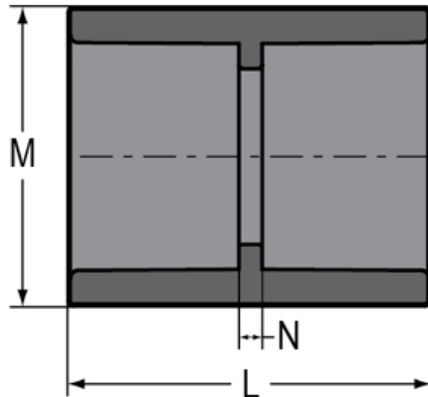

**Connection** Socket x Socket  
**Type** Standard

**L** = 2-11/32

**M** = 1-31/32

**N** = 3/32

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

