

Part No: 429-040UV

Schedule 40 UVR

Coupling

Desc: 4 PVC UVR COUPLING SOC SCH40

MSRP: 142.44

Part Code: 042

Weight(lbs): 0.818


Weight(kg): 0.371

Weight(gm): 371

Size: 4"

Color: BEIGE

Material: PVC

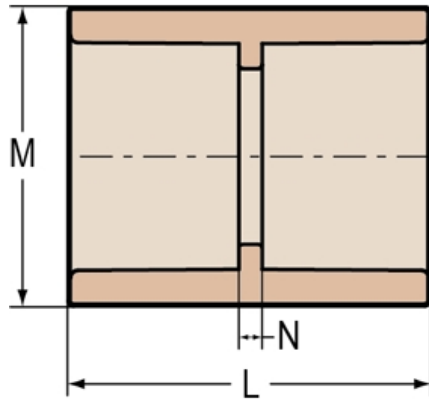

Connection Socket x Socket

Type Coupling

L = 4- 1/4

M = 5- 1/32

N = 3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

