

Part No: 429-626FE

Fabricated Fittings

Coupling

Desc: 10X6 PVC RED COUP ECC SOC SCH40

MSRP: 345.33

Part Code: 047

Weight(lbs): 7.487

Weight(kg): 3.396

Weight(gm): 3396

Size: 10"X6"


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Socket

Type Eccentric Reducer

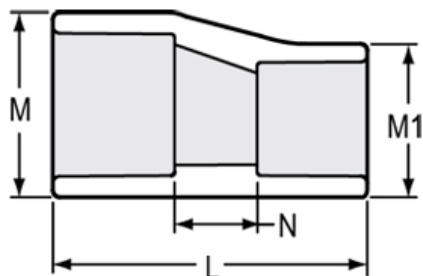

L = 17- 1/8

M = 11- 3/8

M1 = 7- 1/4

N = 8- 5/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

