

**Part No:** 430-010SR

**Schedule 40 White**

**Coupling**

**Desc:** 1 PVC COUPLING SRFPT SCH40

**MSRP:** 9.42

**Part Code:** 046

**Weight(lbs):** 0.134

**Weight(kg):** 0.061

**Weight(gm):** 61


**Size:** 1"

**Color:** WHITE

**Material:** PVC

**Connection** SR Fipt x SR Fipt

**Type** Standard

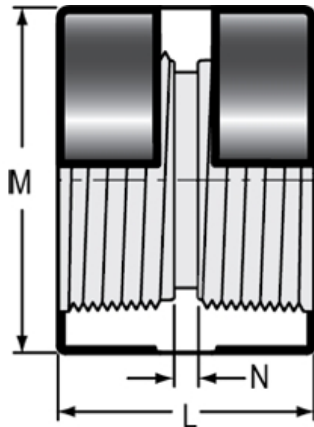

**L** = 1-15/16

**M** = 1-11/16

**N** = 5/32

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

