

Part No: 43063S-140C

Fume & Air Duct

Elbow

Desc: 14 CPVC 90 ELL 3 SGMT SOC DUCT SMACNA

MSRP: 1372.84

Part Code: 433

Weight(lbs): 18.755

Weight(kg): 8.507

Weight(gm): 8507


Size: 14

Color: GRAY

Material: CPVC

Type 90° Elbow 3-Piece (SMACNA)

Connection Belled Socket

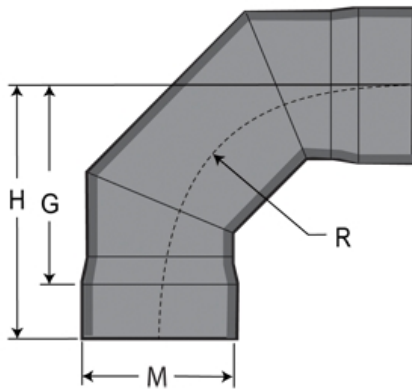

G = 21

H = 23-1/2

M = 14-3/8

R = 21

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

