

Part No: 43065-060C

Fume & Air Duct

Elbow

Desc: 6 CPVC 90 EL5 SEG SOC DUCT SMACNA

MSRP: 512.87

Part Code: 432

Weight(lbs): 4.63

Weight(kg): 2.1

Weight(gm): 2100


Size: 6

Color: GRAY

Material: CPVC

Type 90° Elbow 5-Piece (SMACNA)

Connection Belled Socket

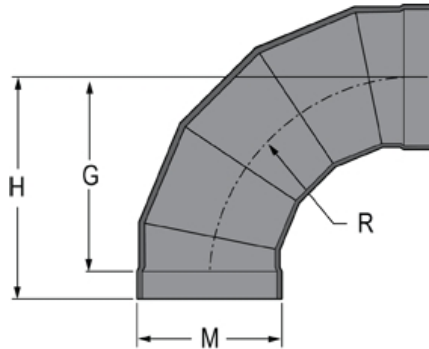

G = 9-7/8

H = 12-3/8

M = 7

R = 9

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

