

Part No: 431-120F

Fabricated Fittings

Adapter

Desc: 12 PVC ADAPTER IPSXPIP SPGXSOC SCH40 FAB

MSRP: 119.44

Part Code: 047

Weight(lbs): 3.613

Weight(kg): 1.639

Weight(gm): 1639

Size: 12"


Color: WHITE

Material: PVC

Schedule SCH 40

Connection Socket X Fipt

Type Standard

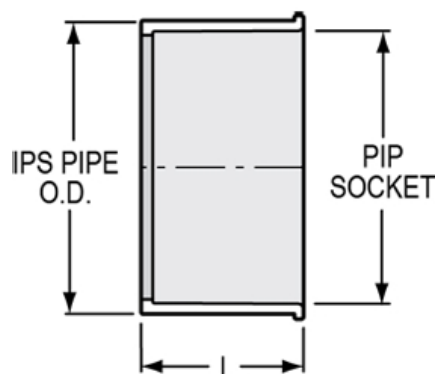

L = 6-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

