

Part No: 43173-100C

Fume & Air Duct

Elbow

Desc: 10 CPVC 3PC 45 ELL SOC DCT SMACNA

MSRP: 727.81

Part Code: 432

Weight(lbs): 6.296

Weight(kg): 2.856

Weight(gm): 2856


Size: 10

Color: GRAY

Material: CPVC

Type 45° Elbow 3-Piece (SMACNA)

Connection Belled Socket

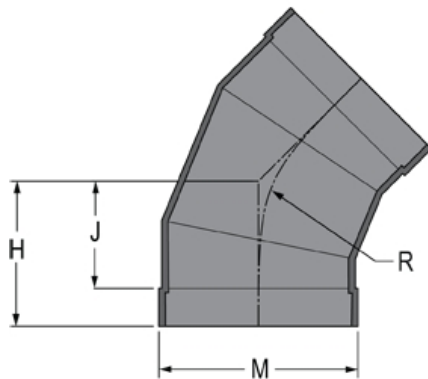

H = 8-13/16

J = 6-5/16

M = 11-1/8

R = 15

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

