

Part No: 43173-140C

Fume & Air Duct

Elbow

Desc: 14 CPVC 3PC 45 ELBOW SOC DUCT SMACNA

MSRP: 1201.21

Part Code: 432

Weight(lbs): 9.606

Weight(kg): 4.357

Weight(gm): 4357


Size: 14

Color: GRAY

Material: CPVC

Type 45° Elbow 3-Piece (SMACNA)

Connection Belled Socket

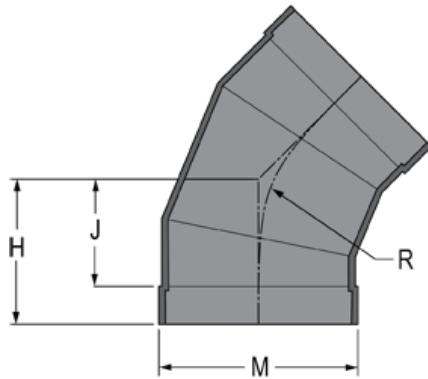

R = 21

H = 10-5/16

J = 7-13/16

M = 14-3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

