

Part No: 43173-200

Fume & Air Duct

Elbow

Desc: 20 PVC 3PC 45 ELL SOC DUCT SMACNA

MSRP: 1293.01

Part Code: 430

Weight(lbs): 17.659

Weight(kg): 8.01

Weight(gm): 8010


Size: 20

Color: GRAY

Material: PVC

Type 45° Elbow 3-Piece (SMACNA)

Connection Belled Socket

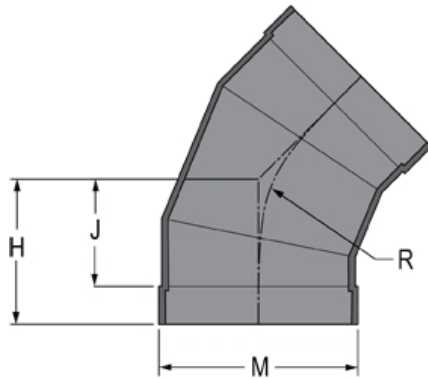

H = 12-15/16

J = 10-7/16

M = 20-7/16

R = 30

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

