

**Part No:** 43173-200C

**Fume & Air Duct**

**Elbow**

**Desc:** 20 CPVC 3PC 45 ELBOW SOC DUCT SMACNA

**MSRP:** 2371.01

**Part Code:** 432

**Weight(lbs):** 19.833

**Weight(kg):** 8.996

**Weight(gm):** 8996


**Size:** 20

**Color:** GRAY

**Material:** CPVC

**Type** 45° Elbow 3-Piece (SMACNA)

**Connection** Belled Socket

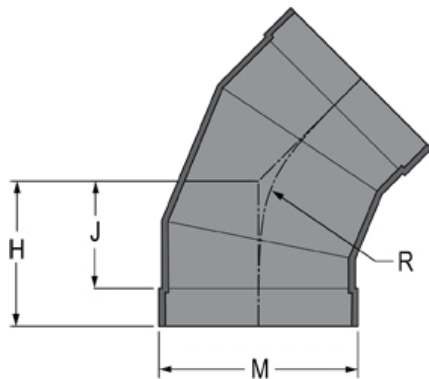

**H** = 12-15/16

**J** = 10-7/16

**M** = 20-7/16

**R** = 30

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  inch & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

