

Part No: 4329C-762

Fume & Air Duct

Coupling

Desc: 16X12 PVC CONICAL RED SOC DUCT

MSRP: 456.13

Part Code: 431

Weight(lbs): 4.193

Weight(kg): 1.902

Weight(gm): 1902


Size: 16X12

Color: GRAY

Material: PVC

Type Conical Reducer Coupling

Connection Belled Socket

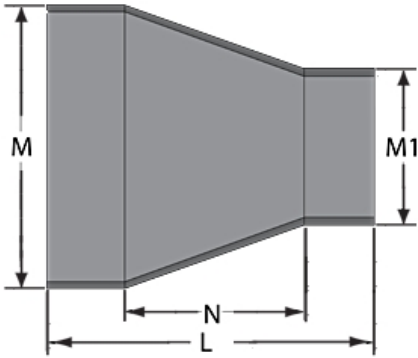

L = 9-1/2

M = 16-3/8

M1 = 13-1/8

N = 4-1/2

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

