

Part No: 4329C-824C

Fume & Air Duct

Coupling

Desc: 20X14 CPVC CONICAL RED SOC DUCT

MSRP: 1603.98

Part Code: 433

Weight(lbs): 6.612

Weight(kg): 2.999

Weight(gm): 2999


Size: 20X14

Color: GRAY

Material: CPVC

Type Conical Reducer Coupling

Connection Belled Socket

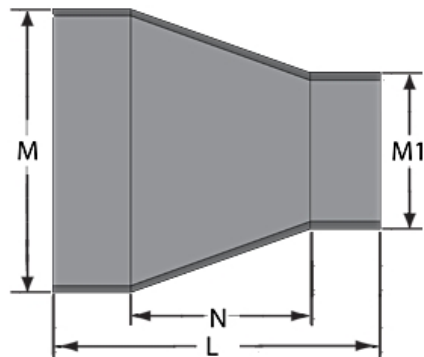

L = 13-5/16

M = 20-7/16

M1 = 14-3/8

N = 8-5/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

