

Part No: 4329C-910C

Fume & Air Duct

Coupling

Desc: 24X10 CPVC CONICAL REDUCER SOC DUCT

MSRP: 1986.29

Part Code: 433

Weight(lbs): 8.834

Weight(kg): 4.007

Weight(gm): 4007


Size: 24X10

Color: GRAY

Material: CPVC

Type Conical Reducer Coupling

Connection Belled Socket

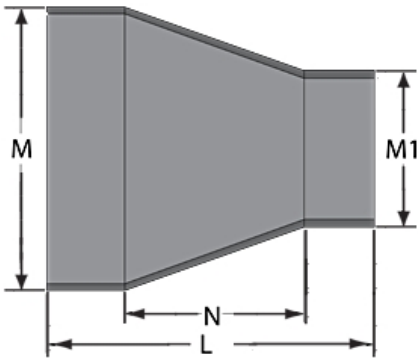

L = 23-1/4

M = 24-1/2

M1 = 11-1/8

N = 18-1/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

