

Part No: 4347-100A

Fume & Air Duct

Rain Cap

Desc: 10 PVC RAIN CAP "A" STYLE SOC DUCT

MSRP: 1150.21

Part Code: 430

Weight(lbs): 8.069

Weight(kg): 3.66

Weight(gm): 3660


Size: 10

Color: GRAY

Material: PVC

Type Rain Cap Style "A"

Connection Belled Socket

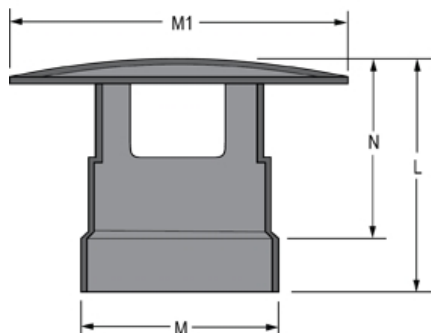

L = 12-3/8

M = 11-1/8

M1 = 20

N = 9- 7/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

