

Part No: 4347-200BC

Fume & Air Duct

Rain Cap

Desc: 20 CPVC RAIN CAP "B" STYLE SOC DUCT

MSRP: 7000.42

Part Code: 432

Weight(lbs): 100.445

Weight(kg): 45.561

Weight(gm): 45561


Size: 20

Color: GRAY

Material: CPVC

Type Rain Cap Style "B"

Connection Belled Socket

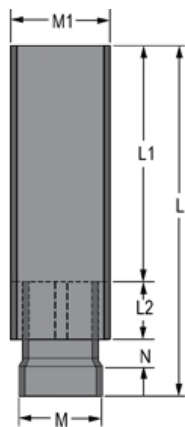

L = 90-1/2

L1 = 80

L2 = 6

M = 20-7/16

M1 = 24

N = 2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

