

Part No: 4347-240A

Fume & Air Duct

Rain Cap

Desc: 24 PVC RAIN CAP SOC "A" STYLE DUCT

MSRP: 2290.26

Part Code: 430

Weight(lbs): 60.44

Weight(kg): 27.415

Weight(gm): 27415


Size: 24

Color: GRAY

Material: PVC

Type Rain Cap Style "A"

Connection Belled Socket

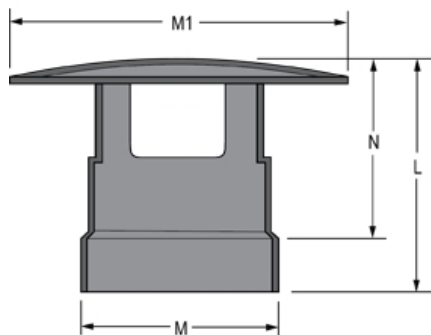

L = 25-1/16

M = 24-1/2

M1 = 48

N = 22-9/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

