

Part No: 4347-240AC

Fume & Air Duct

Rain Cap

Desc: 24 CPVC RAIN CAP "A" STYLE SOC DUCT

MSRP: 7695.93

Part Code: 432

Weight(lbs): 63.189

Weight(kg): 28.662

Weight(gm): 28662


Size: 24

Color: GRAY

Material: CPVC

Type Rain Cap Style "A"

Connection Belled Socket

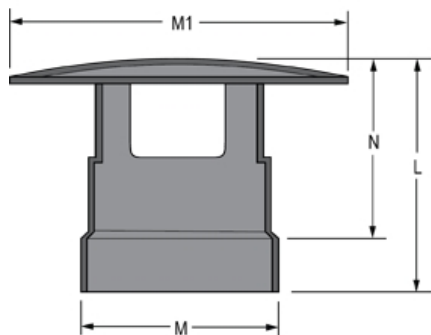

L = 25-1/16

M = 24-1/2

M1 = 48

N = 22-9/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

