

Part No: 435-003

Schedule 40 White

Adapter

Desc: 3/8 PVC FEMALE ADAPTER SOCXFPT SCH40

MSRP: 3.96

Part Code: 040

Weight(lbs): 0.033


Weight(kg): 0.015

Weight(gm): 15

Size: 3/8"

Color: WHITE

Material: PVC

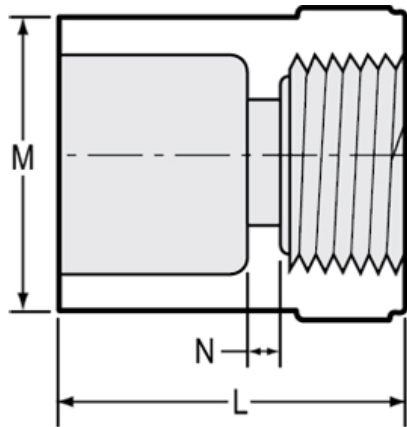

L = 1- 7/16

M = 1

N = 3/32

Connection Socket x Fipt

Type Standard

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

