

Part No: 435-007B

Schedule 40 Black

Adapter

Desc: 3/4 PVC FEM ADAPTER SOCXFPT SCH40 BLACK

MSRP: 1.62

Part Code: 011

Weight(lbs): 0.049


Weight(kg): 0.022

Weight(gm): 22

Size: 3/4"

Color: BLACK

Material: PVC Black

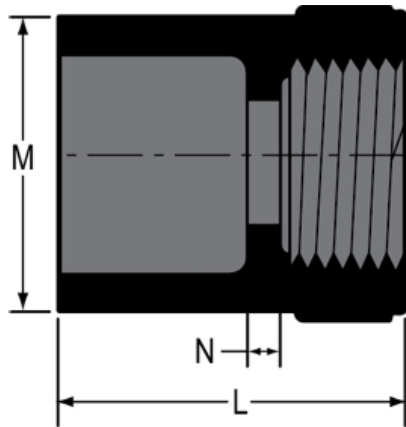

N = 3/32

L = 1-13/16

M = 1-5/16

Connection Socket x Fipt

Type Female Adapter

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

