

Part No: 435-007SRL

Schedule 40 Clear

Adapter

Desc: 3/4 PVC FEM ADAPTER SOCXSRFPT SCH40 CLR

MSRP: 16.12

Part Code: 039

Weight(lbs): 0.077


Weight(kg): 0.035

Weight(gm): 35

Size: 3/4"

Color: CLEAR

Material: PVC Clear

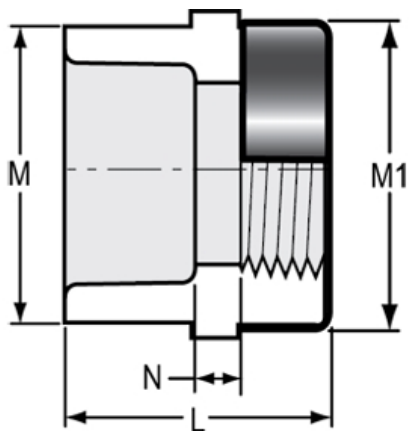

Connection Socket x SR Fipt

Type Female Adapter

N = 3/32

L = 1- 7/8

M = 1-13/32

M1 = 1- 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

