

Part No: 435-007UV

Schedule 40 UVR

Adapter

Desc: 3/4 PVC UVR FEMALE ADAPTER SOCXFPT SCH40

MSRP: 5.64

Part Code: 042

Weight(lbs): 0.044


Weight(kg): 0.02

Weight(gm): 20

Size: 3/4"

Color: BEIGE

Material: PVC UVR

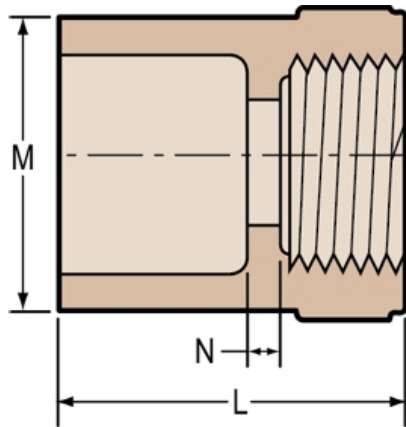

L = 1-13/16

M = 1-5/16

N = 3/32

Type Female Adapter
Connection Socket x Fipt

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

