

Part No: 435-010SRT

EverTUFF® TURF™

Adapter

Desc: 1 PVC FEMALE ADPT SOCXSRFPT CL315

MSRP: 16.92

Part Code: 031

Weight(lbs): 0.146

Weight(kg): 0.066

Weight(gm): 66


Size: 1"

Color: BLUE

Material: PVC

Connection Socket x SR Fipt

Type SR Female Adapter

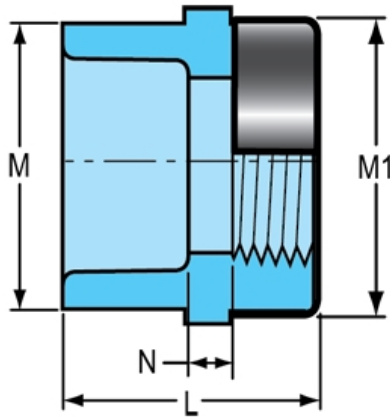

L = 2- 5/32

M = 1- 3/16

M1 = 1-25/32

N = 3/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

