

Part No: 435-012G

Schedule 40 Gray

Adapter

Desc: 1-1/4 PVC FEM ADAPTER SOCXFPT SCH40 GRAY

MSRP: 3.04

Part Code: 043

Weight(lbs): 0.115


Weight(kg): 0.052

Weight(gm): 52

Size: 1-1/4"

Color: GRAY

Material: PVC

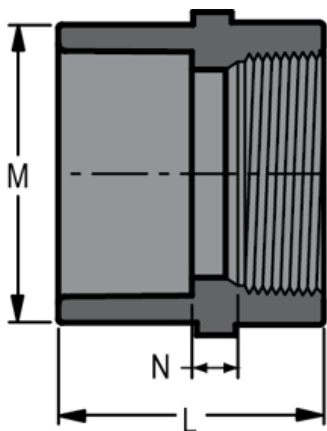

Connection Socket x Fipt

Type Standard

L = 2- 9/32

M = 1-31/32

N = 1/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

