

**Part No:** 435-015B

**Schedule 40 Black**

**Adapter**

**Desc:** 1-1/2 PVC FEM ADAPTER SOCXFPT SCH40 BLCK

**MSRP:** 3.37

**Part Code:** 011

**Weight(lbs):** 0.139


**Weight(kg):** 0.063

**Weight(gm):** 63

**Size:** 1-1/2"

**Color:** BLACK

**Material:** PVC Black

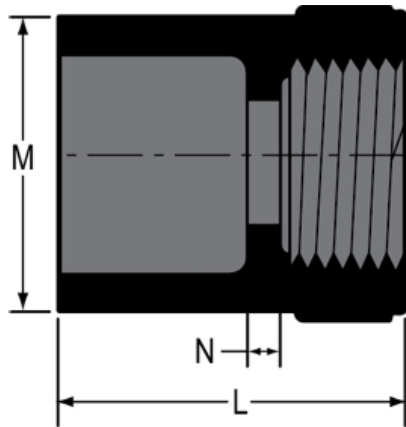

**L** = 2- 5/16

**M** = 2- 7/32

**N** = 3/32

**Connection** Socket x Fipt

**Type** Female Adapter

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

