

Part No: 435-025SRL

Schedule 40 Clear

Adapter

Desc: 2-1/2 PVC FEM ADPTER SOCXSRFPT SCH40 CLR

MSRP: 93.93

Part Code: 039

Weight(lbs): 0.657


Weight(kg): 0.298

Weight(gm): 298

Size: 2-1/2"

Color: CLEAR

Material: PVC Clear

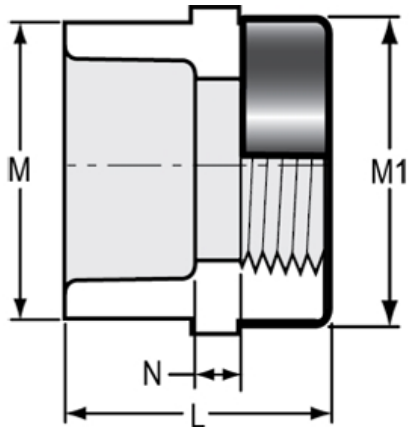

Connection Socket x SR Fipt

Type Female Adapter

L = 3- 1/4

M = 3- 9/16

M1 = 3- 9/16

N = 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

