

Part No: 435-050G

Schedule 40 Gray

Adapter

Desc: 5 PVC GRAY FEMALE ADAPTER SOCXFPT SCH40

MSRP: 68.89

Part Code: 043

Weight(lbs): 1.444

Weight(kg): 0.655

Weight(gm): 655


Size: 5"

Color: GRAY

Material: PVC

Connection Socket x Fipt

Type Standard

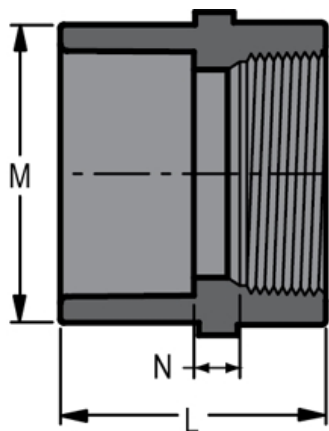

L = 5- 1/16

M = 6- 5/16

N = 3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

