

Part No: 435-060SRT

EverTUFF® TURF™

Adapter

Desc: 6 PVC FEMALE ADPT SOCXSRFPT CLASS 315

MSRP: 233.18

Part Code: 031

Weight(lbs): 3.314


Weight(kg): 1.503

Weight(gm): 1503

Size: 6

Color: BLUE

Material: PVC

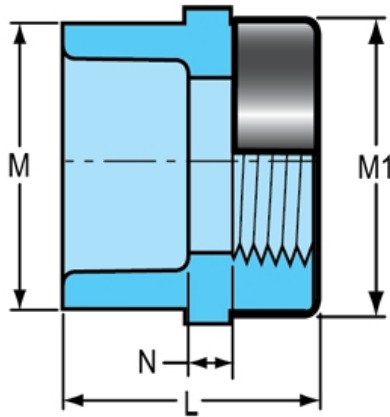

Connection Socket x SR Fipt
Type SR Female Adapter

L = 5

M = 7-21/32

M1 = 7-21/32

N = 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

