

Part No: 435-098

Schedule 40 White

Adapter

Desc: 3/4X1/4 PVC FEMALE ADAPTER SOCXFPT SCH40

MSRP: 3.01

Part Code: 040

Weight(lbs): 0.057


Weight(kg): 0.026

Weight(gm): 26

Size: 3/4 X 1/4

Color: WHITE

Material: PVC

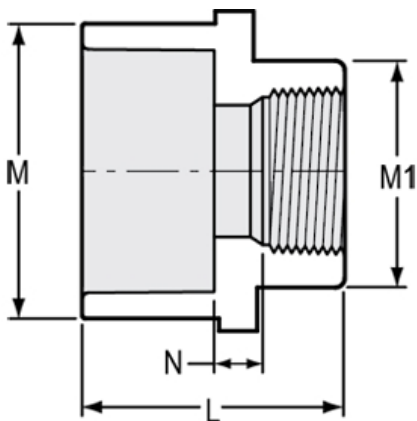

Connection Socket x Fipt

Type Reduction

L = 1-15/16

M = 1-13/32

M1 = 27/32

N = 11/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

