

Part No: 435-582F

Fabricated Fittings

Adapter

Desc: 8X4 PVC RED FEMALE ADAPTER SOCXFPT SCH40

MSRP: 296.64

Part Code: 047

Weight(lbs): 6.614


Weight(kg): 3

Weight(gm): 3000

Size: 8"X4"

Color: WHITE

Material: PVC

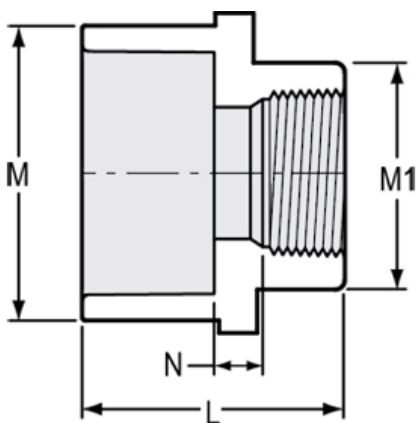

Schedule SCH 40
Connection Socket X Fipt
Type Reduction

L = 11-1/2

M = 9-1/8

M1 = 7-3/16

N = 5-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

