

Part No: 435-628F

Fabricated Fittings

Adapter

Desc: 10X8 PVC RED FEMALE ADAPT SOCXFPT SCH40

MSRP: 324.67

Part Code: 047

Weight(lbs): 9.259


Weight(kg): 4.2

Weight(gm): 4200

Size: 8"X10"

Color: WHITE

Material: PVC

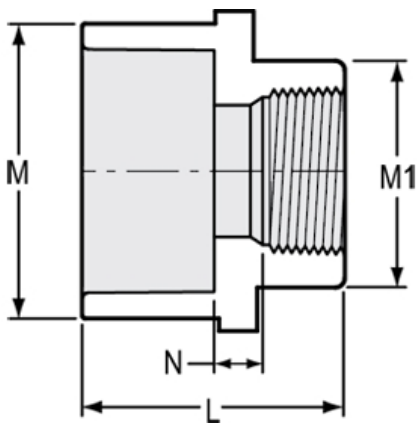

L = 11-3/4

M = 11-3/4

M1 = 9-1/4

N = 4-13/16

Schedule SCH 40

Connection Socket X Fipt

Type Reduction

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

