

Part No: 4351S-180C

Fume & Air Duct

Flange

Desc: 18 CVC SOLID FLG SOC DUCT SMACNA

MSRP: 936.93

Part Code: 432

Weight(lbs): 8.878

Weight(kg): 4.027

Weight(gm): 4027


Size: 18

Color: GRAY

Material: CPVC

Type Flange (SMACNA)

Connection Belled Socket (One Piece)

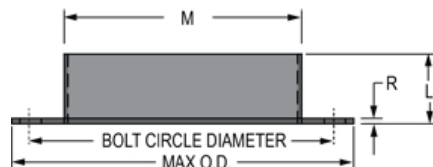

L = 2-3/4

M = 18-3/8

R = 1/4

Max. = 22
O.D.

No of = 20
Bolts

Hole Size = 5/16

Bolt
Circle = 20-1/2
Dia.

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

