

Part No: 4351S-200

Fume & Air Duct

Flange

Desc: 20 PVC SOLID FLG SOC DUCT SMACNA

MSRP: 613.09

Part Code: 430

Weight(lbs): 4.079

Weight(kg): 1.85

Weight(gm): 1850


Size: 20

Color: GRAY

Material: PVC

Type Flange (SMACNA)

Connection Belled Socket (One Piece)

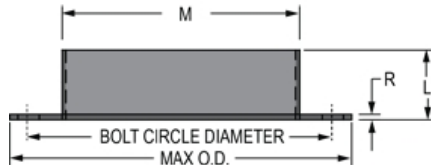

L = 2-3/4

M = 20-7/16

R = 1/4

Max. = 24
O.D.

No of = 22
Bolts

Hole Size = 5/16

Bolt = 22-1/2
Circle
Dia.

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

