

Part No: 436-100F

Fabricated Fittings

Adapter

Desc: 10 PVC MALE ADAPTER MPTXSOC SCH40

MSRP: 350.27

Part Code: 047

Weight(lbs): 11.171


Weight(kg): 5.067

Weight(gm): 5067

Size: 10"

Color: WHITE

Material: PVC

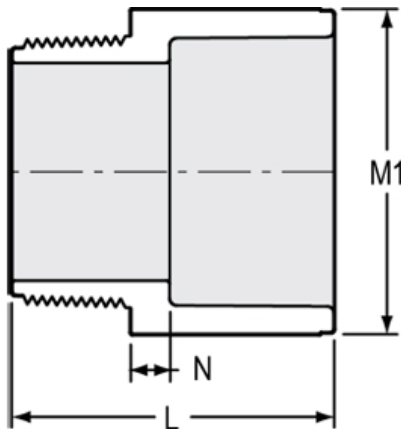

L = 10- 3/8

M1 = 11-15/16

N = 3- 3/16

Schedule SCH 40

Connection Mipt X Socket

Type Standard

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

