

Part No: 43BG-060C

Fume & Air Duct

Blast Gate

Desc: 6 CPVC BLAST GATE SOC DUCT

MSRP: 710.34

Part Code: 432

Weight(lbs): 4.101

Weight(kg): 1.86

Weight(gm): 1860


Size: 6

Color: GRAY

Material: CPVC

Type Blast Gate

Connection Belled Socket

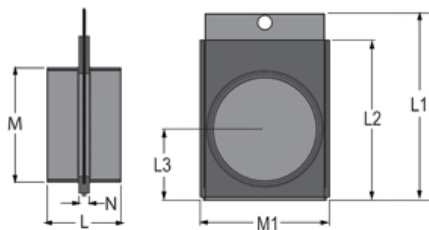

L = 5-3/4

L1 = 12-3/8

L2 = 10-1/4

L3 = 4-1/2

M = 7

M1 = 8-3/4

N = 15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

