

Part No: 43BG-080

Fume & Air Duct

Blast Gate

Desc: 8 PVC BLAST GATE SOC DUCT

MSRP: 493.6

Part Code: 430

Weight(lbs): 4.564

Weight(kg): 2.07

Weight(gm): 2070


Size: 8

Color: GRAY

Material: PVC

Type Blast Gate

Connection Belled Socket

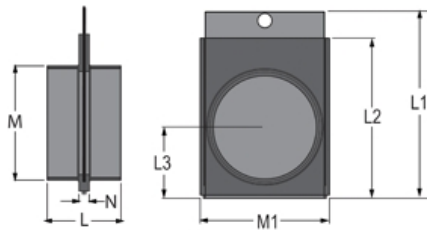

L = 5-13/16

L1 = 14-11/16

L2 = 12-5/8

L3 = 5-5/8

M = 9

M1 = 10-3/16

N = 13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

