

Part No: 43BG-160C

Fume & Air Duct

Blast Gate

Desc: 16 CPVC BLAST GATE SOC DUCT

MSRP: 1705.1

Part Code: 432

Weight(lbs): 13.17

Weight(kg): 5.974

Weight(gm): 5974


Size: 16

Color: GRAY

Material: CPVC

Type Blast Gate

Connection Belled Socket

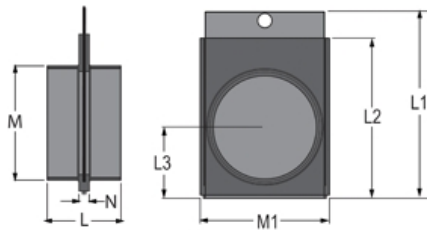

L = 5-5/8

L1 = 22-1/4

L2 = 20-3/4

L3 = 9-1/2

M = 16-3/8

M1 = 16-3/4

N = 5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

