

Part No: 43BG-200

Fume & Air Duct

Blast Gate

Desc: 20 PVC BLAST GATE SOC DUCT

MSRP: 1294.68

Part Code: 430

Weight(lbs): 18.594

Weight(kg): 8.434

Weight(gm): 8434


Size: 20

Color: GRAY

Material: PVC

Type Blast Gate

Connection Belled Socket

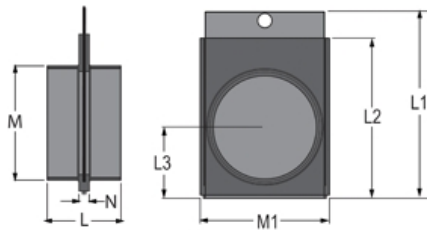

L = 5-5/8

L1 = 29

L2 = 26-1/4

L3 = 11-1/2

M = 20-7/16

M1 = 25-1/8

N = 5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

